


## Schlauchtüllen

## Hose nipples

## Raccords de tuyau

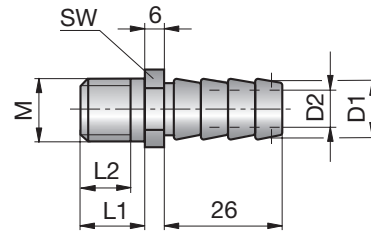

**Z7720-**

Mat.: Ms

Z7720-Type





Type	M	L1	L2	D2	D1	SW
1	M10 x 1	18	12	6	10,5	12
2	G 1/8 A	18	12	6	10,5	12
3	G 1/4 A	18	12	8	13,5	14
4	M10 x 1	32	12	6	10,5	12
5	G 1/8 A	32	12	6	10,5	12
6	G 1/4 A	32	12	8	13,5	14

## Temperierrohre

## Cooling tubes

## Tube de refroidissement

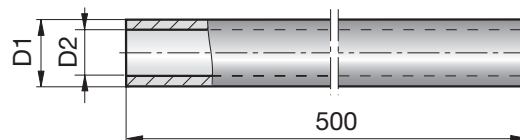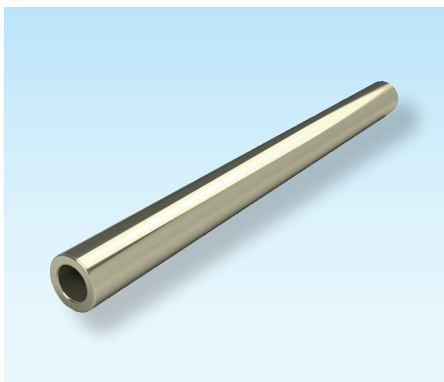

**Z7725-**

Mat.: Ms

Z7725-D1



D1	D2
4	2,5
6	3,5
8	5
10	6
12	8
14	10