


SERIES 66



**“TR” POLYURETHANE WHEELS,
POLYAMIDE 6 CENTRE,
SWIVEL TOP PLATE BRACKET TYPE “P”**

Wheel description

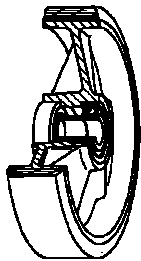


Tread: “TR” polyurethane tread, hardness 95+/-3 Shore A; excellent rolling resistance and elasticity, highly resistant to wear and to tearing.

Centre: polyamide 6.

Hub: the hub is available with plain bearing and with roller bearing.

Bracket description

Medium-heavy duty bracket type P (max. carrying capacity 750 daN)

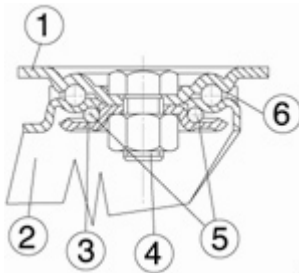

- 1) **Plate:** electrolytically galvanised steel plate
 - 2) **Fork:** electrolytically galvanised steel plate
 - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
 - 4) **King Pin:** steel screw class 8.8 and nut
 - 5) **Swivel actions:** double ring of greased balls
 - 6) **Dust seal:** red polyamide
- Finishing:** yellow galvanisation
Fitting: top plate