
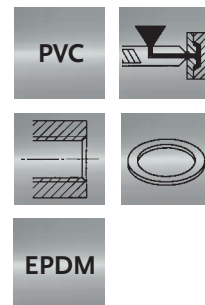
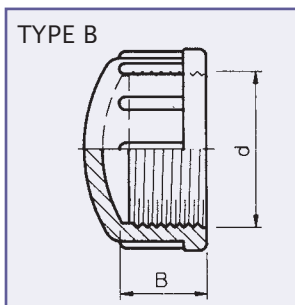
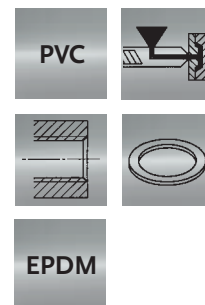


Screwcap

Draadkap
Schraubkappe
Bouchon taraudé
Calotta a filetto
Tapon rosco hembra



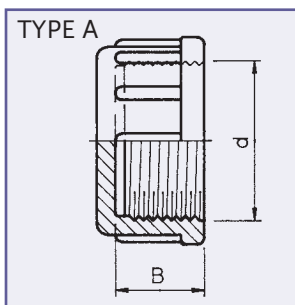


PVC-u metric

Art.code	d	B	Type	PN	Quantity
3.40.010	3/8" (F)	13	A	10	250 (5x50)
3.40.020	1/2" (F)	14	A	10	500 (10x50)
3.40.030	3/4" (F)	16	A	10	400 (8x50)
3.40.040	1" (F)	17	A	10	500 (10x50)
3.40.050	1 1/4" (F)	19	A	10	500 (10x50)
3.40.060	1 1/2" (F)	23	B	10	300
3.40.062	1 1/2" (F)	23	A	10	300
3.40.070	2" (F)	24	B	10	150
3.40.072	2" (F)	24	A	10	150
3.40.075	2 1/4" (F)	25	A	10	25
3.40.080	2 1/2" (F)	29	B	10	100
3.40.082	2 1/2" (F)	29	A	10	100
3.40.085	2 3/4" (F)	29	A	10	25
3.40.090	3" (F)	31	B	10	50
3.40.092	3" (F)	31	A	10	50
3.40.100	4" (F)	34	B	6	10
3.40.102	4" (F)	34	A	6	10

Plug

Draadstop
Gewindestopfen
Bouchon fileté
Tappo
Tapon rosco macho

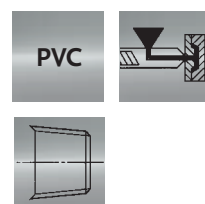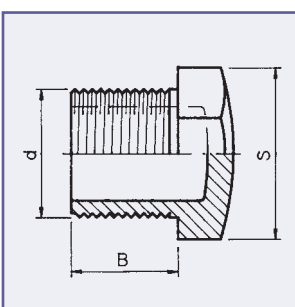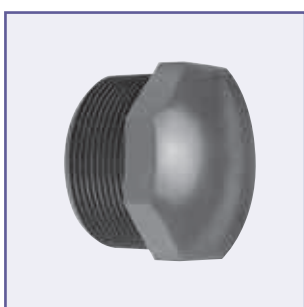

Art.code	d	B	S	PN	Quantity
3.45.025	1/4" (M)	12	17	16	100
3.45.030	3/8" (M)	14	22	16	100
3.45.040	1/2" (M)	18	27	16	100
3.45.045	3/4" (M)	19	32	16	100
3.45.050	1" (M)	22	36	16	100
3.45.055	1 1/4" (M)	24	46	16	100
3.45.060	1 1/2" (M)	24	55	16	100
3.45.065	2" (M)	27	65	16	100
3.45.070	2 1/2" (M)	31	94	10	25
3.45.075	3" (M)	34	114	10	25
3.45.080	4" (M)	40	138	10	25