

Adaptor socket






Draadsok

Schraubmuffe

Manchon taraudé

Manicotto

Manguito transición

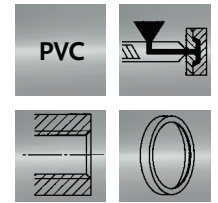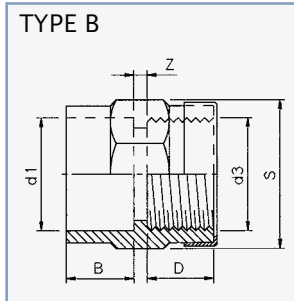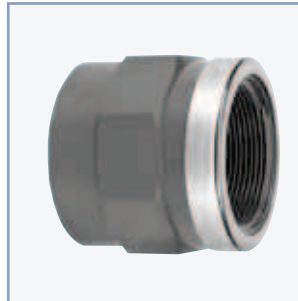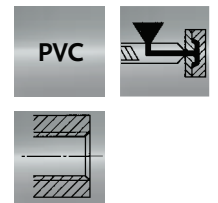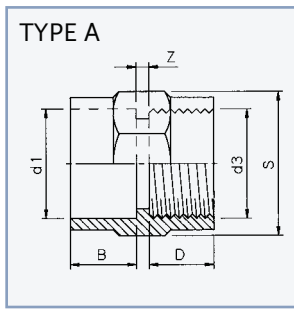

Art.code	(inch) d1	d3	Z	B	D	S	Type	PN	Quantity
3.24.019	1/2	1/4" (F)	4	17	12	32	A	16	100
3.24.020	1/2	3/8" (F)	4	17	12	32	A	16	100
3.24.021	1/2	1/2" (F)	1	17	15	32	B	16	50
3.24.029	3/4	3/8" (F)	7	20	12	36	A	16	100
3.24.030	3/4	1/2" (F)	4	20	15	36	A	16	100
3.24.031	3/4	3/4" (F)	3	20	16	36	B	16	50
3.24.044	1	1/2" (F)	5	23	15	46	B	16	50
3.24.045	1	3/4" (F)	6	23	16	46	B	16	75
3.24.046	1	1" (F)	2	23	22	46	B	16	50
3.24.054	1 1/4	3/4" (F)	4	28	16	55	B	16	50
3.24.055	1 1/4	1" (F)	2	28	22	55	B	16	50
3.24.056	1 1/4	1 1/4" (F)	1	28	23	55	B	16	50
3.24.064	1 1/2	1" (F)	3	30	22	66	B	16	100
3.24.065	1 1/2	1 1/4" (F)	5	30	23	66	B	16	75
3.24.066	1 1/2	1 1/2" (F)	3	30	25	66	B	16	50
3.24.069	2	1 1/4" (F)	5	36	23	80	B	16	50
3.24.070	2	1 1/2" (F)	4	36	25	80	B	16	50
3.24.071	2	2" (F)	4	36	28	80	B	16	25
3.25.077	2 1/2	1 1/2" (F)	5	44	23	94	B	10	40
3.25.079	2 1/2	2" (F)	4	44	28	94	B	10	35
3.25.081	2 1/2	2 1/2" (F)	3	44	31	94	B	10	40