

Raccordi Maschi


Males

Außengewinde-Nippel

**AGJ**

JIC 37° - UNF-UN

ISO 12151-5 (ISO 8434-2)

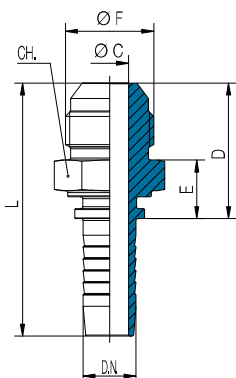

NEW

NEW

NEW


NEW

CODICE Part n° Bestell-Nr.	Filetto Thread Gewinde	Ø F ø F ø F	DN Tubo DN Hose DN Schlauch	CH	L	Ø C	D	E
S 30 15 0 604 006	7/16" - 20 UNF		1/4" 06	14	53,5	4	25,5	11,5
S 30 15 0 606 006	1/2" - 20 UNF		1/4" 06	17	54	4	26	12
S 30 15 0 606 008 A	1/2" - 20 UNF		5/16" 08	14	53,5	5,5	25,5	11,5
S 30 15 0 606 010	1/2" - 20 UNF		3/8" 10	19	55,5	7	26	12
S 30 15 0 608 006 A	9/16" - 18 UNF		1/4" 06	17	53,5	4	25,5	11,5
S 30 15 0 608 008	9/16" - 18 UNF		5/16" 08	19	53,5	5,5	25,5	11,5
S 30 15 0 608 010	9/16" - 18 UNF		3/8" 10	19	55,5	7	26	12
S 30 15 0 610 010	3/4" - 16 UNF		3/8" 10	22	59	7	29,5	13
S 30 15 0 610 013 A	3/4" - 16 UNF		1/2" 12	22	60	9,5	30,5	14
S 30 15 0 610 016 A	3/4" - 16 UNF		5/8" 16	24	65,5	12,5	31,5	15
S 30 15 0 613 010	7/8" - 14 UNF		3/8" 10	24	62,5	7	33	14
S 30 15 0 613 013 A	7/8" - 14 UNF		1/2" 12	24	63,5	9,5	34	14,5
S 30 15 0 613 016 A	7/8" - 14 UNF		5/8" 16	24	68	12,5	34	14,5
S 30 15 0 619 013 A	1 1/16" - 12 UN		1/2" 12	27	67,5	9,5	38	16
S 30 15 0 619 016 A	1 1/16" - 12 UN		5/8" 16	32	72	12,5	38	16
S 30 15 0 613 019	7/8" - 14 UNF		3/4" 19	27	76,5	15	37,5	18
S 30 15 0 619 019 A	1 1/16" - 12 UN		3/4" 19	27	79	15	40	18
S 30 15 0 619 025 A	1 1/16" - 12 UN		1" 25	32	87	15	40	18
S 30 15 0 622 019 A	1 3/16" - 12 UN		3/4" 19	32	79,5	15	40,5	18
S 30 15 0 625 019 A	1 5/16" - 12 UN		3/4" 19	34	80	15	41	18
S 30 15 0 625 025 A	1 5/16" - 12 UN		1" 25	36	88,5	19,5	41,5	18,5
S 30 15 0 632 025 A	1 5/8" - 12 UN		1" 25	42	90	19,5	43	18,5
S 30 15 0 632 032 A	1 5/8" - 12 UN		1 1/4" 31	46	100,5	26	46	21,5
S 30 15 0 638 032 A	1 7/8" - 12 UN		1 1/4" 31	50	105	26	50,5	23
S 30 15 0 638 038 A	1 7/8" - 12 UN		1 1/2" 38	50	109	32	51	23,5
S 30 15 0 650 038	2 1/2" - 12 UN		1 1/2" 38	65	118,5	32	60,5	26,5
S 30 15 0 650 050 A	2 1/2" - 12 UN		2" 51	65	133,5	42	61	27

**AGN**

NPTF

SAE J 518

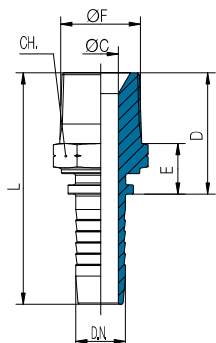

NEW

NEW

NEW

S 30 12 0 504 005	1/8" NPTF		3/16" 05	12	44	3	22	12
S 30 12 0 504 006 A	1/8" NPTF		1/4" 06	12	50	4	22	12
S 30 12 0 506 005	1/4" NPTF		1/4" 05	14	47,5	3	25,5	12
S 30 12 0 506 006	1/4" NPTF		1/4" 06	14	53,5	4	25,5	12
S 30 12 0 506 010 A	1/4" NPTF		3/8" 10	16	55	7	25,5	12
S 30 12 0 510 006 A	3/8" NPTF		1/4" 06	19	54	4	26	12
S 30 12 0 510 008	3/8" NPTF		5/16" 08	19	54	5,5	26	12
S 30 12 0 510 010	3/8" NPTF		3/8" 10	19	56,5	7	27	13
S 30 12 0 510 013 A	3/8" NPTF		1/2" 12	19	57,5	9,5	28	14
S 30 12 0 513 010	1/2" NPTF		3/8" 10	22	61	7	31,5	13
S 30 12 0 513 013 A	1/2" NPTF		1/2" 12	22	62	9,5	32,5	13,5
S 30 12 0 513 016 A	1/2" NPTF		5/8" 16	24	68	12,5	34	15
S 30 12 0 519 013 A	3/4" NPTF		1/2" 12	27	64,5	9,5	35	16
S 30 12 0 519 016	3/4" NPTF		3/4" 16	27	69	12,5	35	16
S 30 12 0 519 019 A	3/4" NPTF		3/4" 19	27	76,5	15	37,5	17,5
S 30 12 0 525 019 A	1" NPTF		3/4" 19	36	80,5	15	41,5	17,5
S 30 12 0 519 025	3/4" NPTF		3/4" 25	32	83,5	19,5	36,5	17,5
S 30 12 0 525 025 A	1" NPTF		1" 25	36	88,5	19,5	41,5	17,5
S 30 12 0 532 025 A	1 1/4" NPTF		1" 25	46	91,5	19,5	44,5	18,5
S 30 12 0 532 032 A	1 1/4" NPTF		1 1/4" 31	46	101	26	46,5	20,5
S 30 12 0 538 038 A	1 1/2" NPTF		1 1/2" 38	50	105,5	32	47,5	20,5
S 30 12 0 550 050 A	2" NPTF		2" 51	65	127,5	42	55	24

Articoli di basso consumo su richiesta

Slow moving articles available on request

Artikel mit geringen Stückzahlen auf Anfrage