
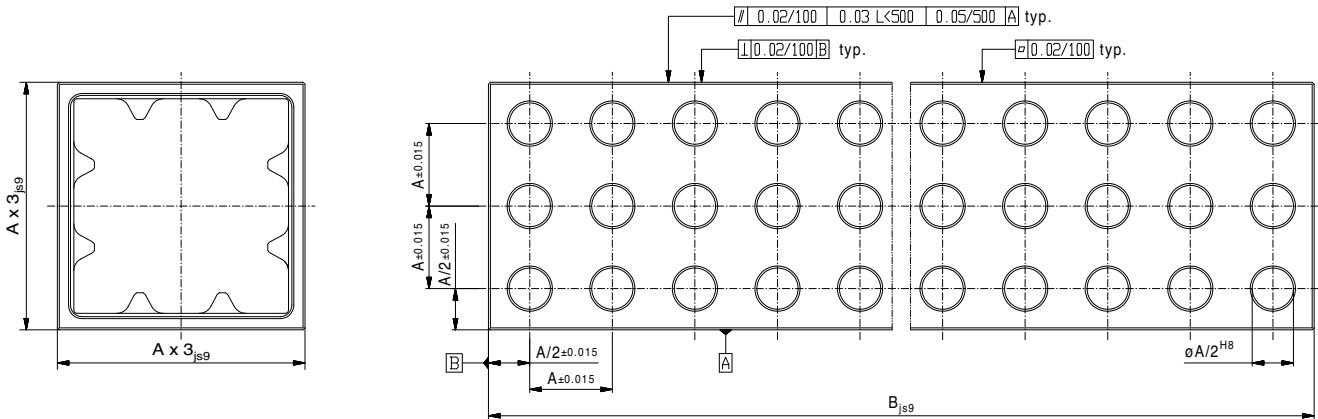


Light bars three row

ALUFIX ECO Light bars are suitable for medium to large fixtures as basic frame material and also for connections direct to the workpiece.

They can be connected using the bores on all 4 sides with quick

or screw connectors, ECO couplings (page 196/197) are used for the face ends.

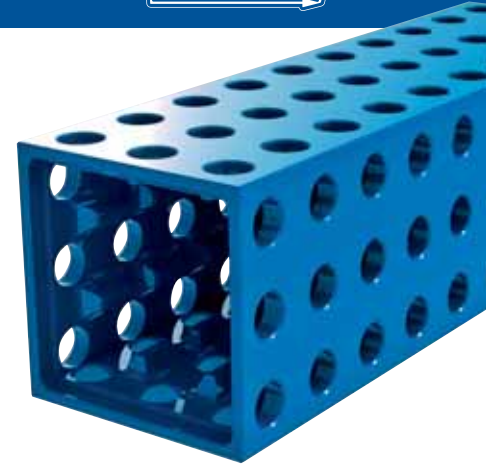

AF25 ECO

A=25, 75 x 75

Nr.	B	
24882-E	100	350
25376-E	200	700
25076-E	300	1.050
27412-E	400	1.410
22618-E	500	1.770
33090-E	600	2.120
31538-E	800	2.830
22621-E	1000	3.500
30751-E	1200	4.200
22624-E	1500	5.300
22771-E	2000	7.000

AF40 ECO

A=40, 120 x 120

Nr.	B	
24950-E	160	1.500
25123-E	200	1.900
24951-E	240	2.200
24952-E	320	3.000
25122-E	360	3.400
23574-E	400	3.700
25124-E	600	5.600
23575-E	800	7.400
27435-E	1000	9.300
23576-E	1200	11.200
23577-E	1600	14.900
23578-E	2000	18.600
23579-E	2400	22.300
27453-E	3000	27.900
23582-E	3600	33.500
23583-E	4000	37.200
23585-E	4800	44.600

AF50 ECO

A=50, 150 x 150

Nr.	B	
28123-E	100	1.400
28124-E	150	2.000
28125-E	200	2.700
27521-E	250	3.400
26817-E	300	4.100
28127-E	400	5.500
26978-E	500	6.800
33302-E	600	8.200
29366-E	800	10.900
26979-E	1000	13.600
33304-E	1200	16.300
26981-E	1500	20.400
26983-E	2000	27.200
26987-E	3000	40.800
26991-E	4000	54.400
26995-E	5000	68.000
26999-E	6000	81.600

